


Data Sheet

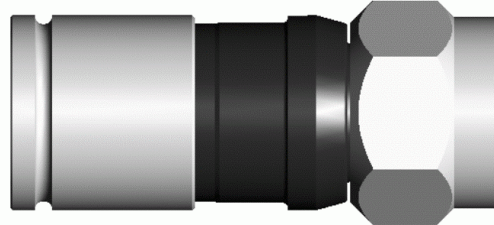

No.	72001000
Connector Type:	EX-6 – 49/83
DRAKA Cable Type:	COAX10 AD 10 S FRNC-C Blau

Band Width:	5 MHz – 2,2GHz
Impedance:	75 Ohm
Amp. Rating:	3 A
Shielding:	>119db @ 900 MHz

Temperature	
Installing:	-5 to +50 °C
Operating:	-40 to +80 °C
Sealing Test:	IP X8

Return Loss: @ MHz, Better Than	
500:	-39 dB
860:	-34 dB
1000:	-32 dB
1750:	-27 dB

Insertion Loss: @ MHz, Better Than	
500:	-0,1 dB
860:	-0,1 dB
1000:	-0,1 dB
1750:	-0,1 dB

Pull Strength:	
Total:	20 kg
Inner Conductor:	X kg
Jacket:	X kg

Dielectric Strength:	2 kV
Insulation Resistance:	(@500V): >29.99Gohm
Inner Conductor:	Resistance max. @ 1A DC: 0.5 mOhm

Material and Plating		
Body:	Brass	NiSn (NiTin)
Inner Cond.		
O'rings	EPDM	
Insulators		